

RESISTENZA A FASCIA PER UGELLO


STRIP HEATER FOR NOZZLE

HEIZEELEMENT FÜR ANGUSSBUCHSE


ERU

- Specifiche:** Su richiesta disponibili con termocoppia a Fascia o a Lamina
- Specifications:** Available on request with Strip or Flat Thermocouple
- Spezifikationen:** Auf Anfrage auch mit flachen oder gewölbten Thermoelementen verfügbar

TIPO A - TYPE A - TYP A

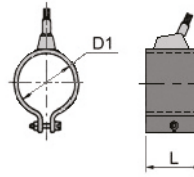

TIPO B - TYPE B - TYP B

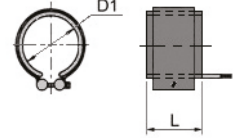

| D1 | L | WATT |
|----|----|------|
| 25 | 30 | 90 |
| 30 | 25 | 90 |
| | 30 | 110 |
| | 35 | 130 |
| | 40 | 150 |
| 35 | 25 | 110 |
| | 30 | 130 |
| | 35 | 150 |
| | 40 | 170 |
| 40 | 45 | 190 |
| | 25 | 125 |
| | 30 | 150 |
| | 35 | 175 |
| 42 | 40 | 220 |
| | 45 | 225 |
| | 25 | 130 |
| | 30 | 160 |
| 45 | 35 | 180 |
| | 40 | 210 |
| | 25 | 140 |
| | 30 | 170 |
| | 35 | 200 |
| 50 | 40 | 230 |
| | 45 | 250 |
| | 50 | 280 |
| | 55 | 310 |

| D1 | L | WATT |
|----|----|------|
| 50 | 20 | 120 |
| | 25 | 150 |
| | 30 | 190 |
| | 35 | 220 |
| | 40 | 250 |
| 55 | 50 | 310 |
| | 60 | 380 |
| | 20 | 140 |
| | 25 | 170 |
| 60 | 30 | 210 |
| | 35 | 240 |
| | 40 | 280 |
| | 50 | 350 |
| | 60 | 450 |

Esempio di ordinativo: Tipo x D1 x L **Order example:** Type x D1 x L **Bestellbeispiel:** Typ x D1 x L