



**Contenitori con viti testa  
martello serie S310 +  
rondelle S370**


# S420

**Set of hammerhead bolts  
complete type S310 +  
washers S370**

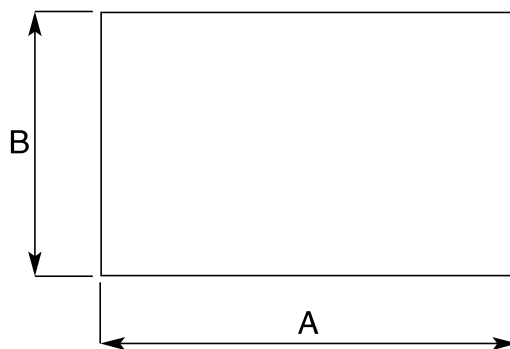

Code			D	Cava	AxB
<b>S420.00010</b>	S310.10040	Nr.2	M10	10	cm
	S310.10060				35x21
	S310.10080				
	S310.10100				
	S310.10125				
	S310.10150				Kg
	S310.10170				3,2
	S370.00010				Nr.10
<b>S420.00012</b>	S310.12040	Nr.2	M12	12	cm
	S310.12050				46x23
	S310.12060				
	S310.12080				
	S310.12100				
	S310.12125				
	S310.12150				
	S310.12170				Kg
S310.12200	5,2				
S370.00012	Nr.10				
<b>S420.00014</b>	S310.14050	Nr.2	M14	14	cm
	S310.14060				50x25
	S310.14080				
	S310.14100				
	S310.14125				
	S310.14150				
	S310.14170				
	S310.14200				Kg
S310.14230	6,5				
S370.00014	Nr.10				
<b>S420.00016</b>	S310.16060	Nr.2	M16	16	cm
	S310.16080				50x25
	S310.16100				
	S310.16125				
	S310.16150				
	S310.16170				
	S310.16200				kg
	S310.16230				8,5
S370.00016	Nr.10				

N.B. : Si eseguono su richiesta misure non a catalogo

Code			D	Cava	AxB	
<b>S420.00018</b>	S310.18080	Nr.2	M18	18	cm	
	S310.18100				50x25	
	S310.18125					
	S310.18150					
	S310.18170					
	S310.18200				Kg	
	S310.18230				8,8	
	S370.00018				Nr.10	
<b>S420.00020</b>	S310.20080	Nr.2	M20	20	cm	
	S310.20100				60x25	
	S310.20125					
	S310.20150					
	S310.20170					
	S310.20200				Kg	
	S310.20230				11,5	
	S370.00020				Nr.10	
<b>S420.00022</b>	S310.22080	Nr.2	M22	22	cm	
	S310.22100				60x25	
	S310.22125					
	S310.22150					
	S310.22170					
	S310.22200				Kg	
	S310.22230				13	
	S370.00022				Nr.10	
<b>S420.00024</b>	S310.24080	Nr.2	M24	24	cm	
	S310.24100				60x25	
	S310.24125					
	S310.24150					
	S310.24170					
	S310.24200				Kg	
	S310.24230				17	
	S370.00024				Nr.10	

N.B. : Other sizes can be supplied on request

